

SM1-Threaded Mounted Telecom Achromatic Doublets


- Holds Ø25.4 mm Achromatic Doublets
- Cell Engraved with Part Number, Focal Length, and Coating



AC254-035-C-ML



AC254-040-C-ML

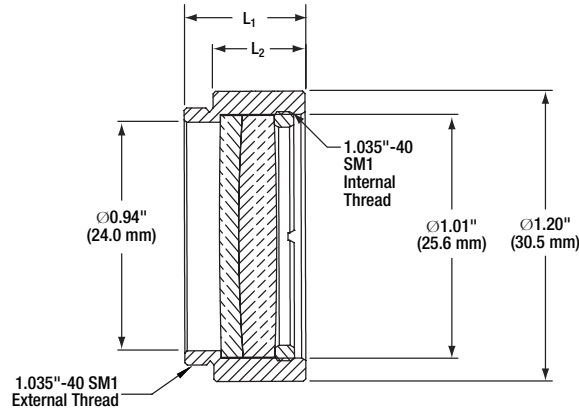

ITEM #	D* (mm)	f (mm)	L ₁ (mm)	L ₂ (mm)	MATERIALS	\$	£	€	RMB
AC254-030-C-ML	25.4	30	0.68	0.56	N-BAF10/N-SF6HT	\$ 110.00	£ 79.20	€ 95.70	¥ 876.70
AC254-035-C-ML	25.4	35	0.68	0.56	N-BAF10/N-SF6HT	\$ 110.00	£ 79.20	€ 95.70	¥ 876.70
AC254-040-C-ML	25.4	40	0.68	0.56	N-LAK22/N-SF6HT	\$ 110.00	£ 79.20	€ 95.70	¥ 876.70
AC254-045-C-ML	25.4	45	0.68	0.56	N-LAK22/N-SF6HT	\$ 110.00	£ 79.20	€ 95.70	¥ 876.70
AC254-050-C-ML	25.4	50	0.62	0.50	N-LAK22/N-SF6HT	\$ 110.00	£ 79.20	€ 95.70	¥ 876.70
AC254-060-C-ML	25.4	60	0.62	0.50	N-LAK22/N-SF6HT	\$ 110.00	£ 79.20	€ 95.70	¥ 876.70
AC254-075-C-ML	25.4	75	0.62	0.50	N-BAF10/N-SF6HT	\$ 110.00	£ 79.20	€ 95.70	¥ 876.70
AC254-100-C-ML	25.4	100	0.56	0.44	N-BAF10/N-SF6HT	\$ 110.00	£ 79.20	€ 95.70	¥ 876.70
AC254-150-C-ML	25.4	150	0.56	0.44	N-BAF10/N-SF6HT	\$ 110.00	£ 79.20	€ 95.70	¥ 876.70
AC254-200-C-ML	25.4	200	0.56	0.44	N-LAK22/N-SF6HT	\$ 110.00	£ 79.20	€ 95.70	¥ 876.70
AC254-250-C-ML	25.4	250	0.56	0.44	SF2/N-SF6HT	\$ 110.00	£ 79.20	€ 95.70	¥ 876.70
AC254-300-C-ML	25.4	300	0.56	0.44	SF2/N-SF6HT	\$ 110.00	£ 79.20	€ 95.70	¥ 876.70
AC254-400-C-ML	25.4	400	0.56	0.44	SF2/N-SF6HT	\$ 110.00	£ 79.20	€ 95.70	¥ 876.70
AC254-500-C-ML	25.4	500	0.49	0.38	SF2/N-SF6HT	\$ 110.00	£ 79.20	€ 95.70	¥ 876.70


*Diameter of Unmounted Lens

SM2-Threaded Mounted Telecom Achromatic Doublets

- Holds Ø50.8 mm Achromatic Doublets
- Cell Engraved with Part Number, Focal Length, and Coating



AC508-1000-C-ML

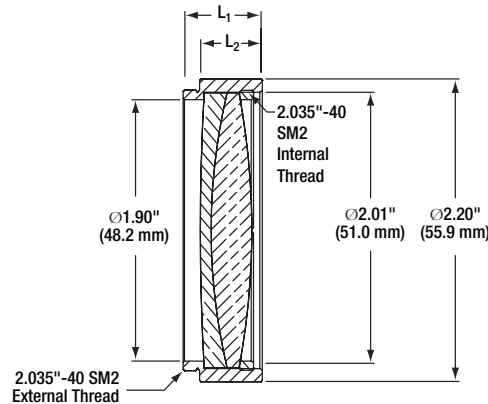

ITEM #	D* (mm)	f (mm)	L ₁ (mm)	L ₂ (mm)	MATERIALS	\$	£	€	RMB
AC508-075-C-ML	50.8	75	1.15	1.03	N-BAF10/N-SF6HT	\$ 186.00	£ 133.92	€ 161.82	¥ 1,482.42
AC508-080-C-ML	50.8	80	1.15	1.03	N-BAF10/N-SF6HT	\$ 186.00	£ 133.92	€ 161.82	¥ 1,482.42
AC508-100-C-ML	50.8	100	1.15	1.03	N-BAF10/N-SF6HT	\$ 186.00	£ 133.92	€ 161.82	¥ 1,482.42
AC508-150-C-ML	50.8	150	1.15	1.03	N-LAK22/N-SF6HT	\$ 186.00	£ 133.92	€ 161.82	¥ 1,482.42
AC508-200-C-ML	50.8	200	0.92	0.80	N-LAK22/N-SF6HT	\$ 186.00	£ 133.92	€ 161.82	¥ 1,482.42
AC508-250-C-ML	50.8	250	0.92	0.80	N-BAF10/N-SF6HT	\$ 186.00	£ 133.92	€ 161.82	¥ 1,482.42
AC508-300-C-ML	50.8	300	0.75	0.63	N-BAF10/N-SF6HT	\$ 186.00	£ 133.92	€ 161.82	¥ 1,482.42
AC508-400-C-ML	50.8	400	0.75	0.63	N-BAF10/N-SF6HT	\$ 186.00	£ 133.92	€ 161.82	¥ 1,482.42
AC508-500-C-ML	50.8	500	0.75	0.63	SF5/N-SF6HT	\$ 186.00	£ 133.92	€ 161.82	¥ 1,482.42
AC508-750-C-ML	50.8	750	0.92	0.80	SF10/N-SF6HT	\$ 186.00	£ 133.92	€ 161.82	¥ 1,482.42
AC508-1000-C-ML	50.8	1000	0.75	0.63	SF5/N-SF6HT	\$ 186.00	£ 133.92	€ 161.82	¥ 1,482.42

*Diameter of Unmounted Lens